


tML<sup>®</sup> - FO partial front plate 5HP with 6x MPO Type B (Key Up/Up) for the Rack Mount Enclosure 3U

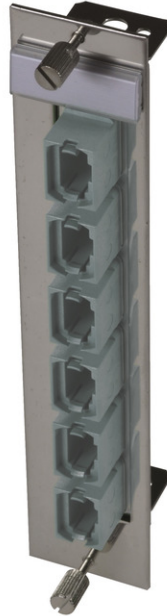

## tML<sup>®</sup> - tde Modular Link

tML<sup>®</sup> is a patented, modular cabling system consisting of the three key components module, trunk cable and rack mount enclosure. The system components are 100 percent manufactured, pre-assembled and tested in Germany. They enable plug-and-play installation on site - especially in data centres, but also in industrial environments - within the shortest possible time. The system is characterized by highest packing density and highest flexibility during migration to higher transmission rates. Fibre optic and TP modules can be combined in one rack mount enclosure. 96x fibre optics LC Duplex or 96x MPO connectors can be used modularly on a 19-inch height unit. Thanks to its patented polarity and dark fibre modules, the tML system offers the simplest migration options to 100G and more.

The tML<sup>®</sup> - FO partial front panel MPO/MTP<sup>®</sup> is intended for the installation in the tML<sup>®</sup> Rack Mount Enclosure 3U.



**tde<sup>®</sup> trans data elektronik GmbH**

**Headquarter address:**

Lingener Str. 2  
D-49626 Bippen/Ohrte  
Tel.: +49 5435 9511 0  
Fax.: +49 5435 9511 32

**Sales office address:**

Prinz-Friedrich-Karl-Str. 46  
D-44135 Dortmund  
Tel.: +49 231 914 36 99  
Fax.: +49 231 914 31 29

info@tde.de | www.tde.de

tML<sup>®</sup> - FO partial front plate 5HP with 6x MPO Type B (Key Up/Up) for the Rack Mount Enclosure 3U

## Technical Data

Pre-mounted	6 x MPO/MTP <sup>®</sup> Adapter (grey)
	QS-Managementsystem ISO 9001, ISO 14001 and TL 9000

## tML<sup>®</sup> - FO partial front panels 5HP

Front Panel	Stainless steel
-------------	-----------------

## FO Adapters

Type	MPO/MTP <sup>®</sup>
Application	Multimode OM1/OM2
Design	without Flange
Connector style	SC Simplex
Key Orientation	Type B, Key up/up
Color	Grey
Material	Plastic
Sleeve	--
Shutter	--
Standards	IEC 61754-7 TIA 604-5
Manufacturer	US Conec

## Product variants & accessories

Art.-No.	Description
TML-T06MP-GN	tML <sup>®</sup> - FO partial front plate 5HP with 6x Type A (Key Up/Down) OS2 green for the Rack Mount Enclosure 3U
TML-T06MP-GR	tML <sup>®</sup> - FO partial front plate 5HP with 6x MPO Type B (Key Up/Up) for the Rack Mount Enclosure 3U
TML-T06MP-LG	tML <sup>®</sup> - FO partial front plate 5HP with 6x MPO Type A (Key Up/Down) OM5 limegreen for the Rack Mount Enclosure 3U
TML-T06MP-TK	tML <sup>®</sup> - FO partial front plate 5HP with 6x MPO Type A (Key Up/Down) OM3 aqua for the Rack Mount Enclosure 3U
TML-T06MP-VI	tML <sup>®</sup> - FO partial front plate 5HP with 6x MPO Type A (Key Up/Down) OM4 magenta for the Rack Mount Enclosure 3U