


N-GxX-xC-03 - PCI Gigabit Ethernet Fiber Network Interface Cards, 1000Base-SX/LX

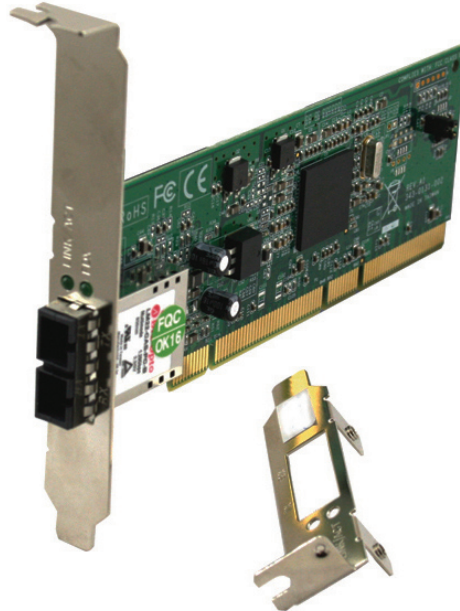

1000Base-LX 1310nm single mode (SC)

[10 km/6.2 mi.] Link Budget: 10.5 dB

Product Description

The N-GxX-xC-03 Gigabit Ethernet NIC provides a 1000Base-SX/LX fiber port, delivering fiber optic connectivity to the desktop for fiber rich LAN environments and works with both 32- and 64-bit PCI 2.2 bus slots. With both standard and low profile form factors, driver support for most common operating systems and plug-and-play capability, installation is a breeze in virtually any PC in your network.

Features

- Supports 32/64-bit PCI 2.2 bus
- Supports 802.1P/Q VLAN filtering function
- Full-duplex flow control
- Plug-and-Play auto-configuration
- TCP, UDP & IP checksum off-loading
- Supports Jumbo Frames up to 9014 bytes



tde[®] trans data elektronik GmbH

Headquarter address:

Lingener Str. 2
D-49626 Bippen/Ohrte
Tel.: +49 5435 9511 0
Fax.: +49 5435 9511 32

Sales office address:

Prinz-Friedrich-Karl-Str. 46
D-44135 Dortmund
Tel.: +49 231 914 36 99
Fax.: +49 231 914 31 29

info@tde.de | www.tde.de

N-GxX-xC-03 - PCI Gigabit Ethernet Fiber Network Interface Cards, 1000Base-SX/LX

- Standard bracket attached, low-profile bracket included
- Supports 802.3ad Link Aggregation (LACP)
- Integrated Remote Boot types supported: PXE, RPL and BOOTP

Show product on manufacturers website: <https://www.transition.com/products/network-adapters/n-gxx-xc-03/>

Technical Data

Specifications

Product variants & accessories

Art.-No.	Description
N-GLX-SC-03	N-GxX-xC-03 - PCI Gigabit Ethernet Fiber Network Interface Cards, 1000Base-SX/LX