


tML[®] - partial front plate with 6x MPO/MTP[®] Type A (Key Up/Down) OM5 limegreen for the Rack Mount Enclosure 1U extendable

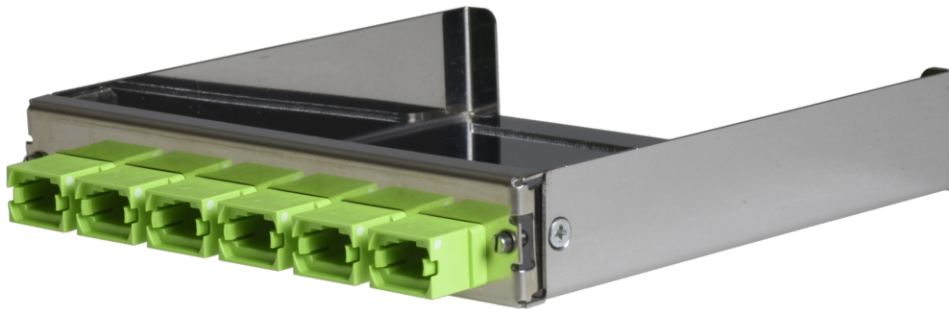

tML[®] - tde Modular Link

tML[®] is a patented, modular cabling system consisting of the three key components module, trunk cable and rack mount enclosure. The system components are 100 percent manufactured, pre-assembled and tested in Germany. They enable plug-and-play installation on site - especially in data centres, but also in industrial environments - within the shortest possible time. The system is characterized by highest packing density and highest flexibility during migration to higher transmission rates. Fibre optic and TP modules can be combined in one rack mount enclosure. 96x fibre optics LC Duplex or 96x MPO connectors can be used modularly on a 19-inch height unit. Thanks to its patented polarity and dark fibre modules, the tML system offers the simplest migration options to 100G and more.

The tML[®] - FO partial front panel is intended for the installation in the tML[®] Rack Mount Enclosure 1U extendable (for 8 x Modules). The tML[®] HD partial front panel can be used only in combination with the tML[®] HD patch cord.



tde[®] trans data elektronik GmbH

Headquarter address:

Lingener Str. 2
D-49626 Bippen/Ohrte
Tel.: +49 5435 9511 0
Fax.: +49 5435 9511 32

Sales office address:

Prinz-Friedrich-Karl-Str. 46
D-44135 Dortmund
Tel.: +49 231 914 36 99
Fax.: +49 231 914 31 29

info@tde.de | www.tde.de

tML[®] - partial front plate with 6x MPO/MTP[®] Type A (Key Up/Down) OM5 limegreen for the Rack Mount Enclosure 1U extendable

Technical Data

Pre-mounted	6 x MPO/MTP [®] Adapter (limegreen)
	QS-Managementsystem ISO 9001, ISO 14001 and TL 9000

tML[®] - FO partial front panels

Front Panel	Stainless steel
Dimensions	108 x 20 mm

FO Adapters

Type	MPO/MTP [®]
Application	Multimode OM5
Design	without Flange
Connector style	SC Simplex
Key Orientation	Type A, Key up/down
Color	Limegreen
Material	Plastic
Sleeve	--
Shutter	--
Standards	IEC 61754-7 TIA 604-5
Manufacturer	US Conec

Product variants & accessories

Art.-No.	Description
TML-M06MP-GN-A8	tML [®] - partial front plate with 6x MPO/MTP [®] Type A (Key Up/Down) OS2 green for the Rack Mount Enclosure 1U extendable
TML-M06MP-GR-A8	tML [®] - partial front plate with 6x MPO/MTP [®] Type B (Key Up/Up) for the Rack Mount Enclosure 1U extendable
TML-M06MP-LG-A8	tML [®] - partial front plate with 6x MPO/MTP [®] Type A (Key Up/Down) OM5 limegreen for the Rack Mount Enclosure 1U extendable
TML-M06MP-TK-A8	tML [®] - partial front plate with 6x MPO/MTP [®] Type A (Key Up/Down) OM3 aqua for the Rack Mount Enclosure 1U extendable
TML-M06MP-VI-A8	tML [®] - partial front plate with 6x MPO/MTP [®] Type A (Key Up/Down) OM4 magenta for the Rack Mount Enclosure 1U extendable