


tDF<sup>®</sup> - FO flex tube holder 3U 12-fold for 6,4mm

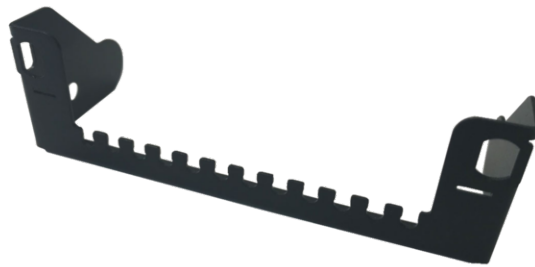

## tDF<sup>®</sup> - tde Distribution Frame (ODF)

tDF<sup>®</sup> is a modular Central Office solution with the highest packing density. At 46U, up to 4032 fibers can be terminated with LC. In developing the tde has taken primarily attention on the user-friendly installation. So the patented modules are fully be fitted from the front. A 19-inch sub rack occupies three height units and is equipped with twelve splice modules. Per sub rack, up to 288 fibers can be terminated with LC. The splices will be stored in standard splice cassettes. A unique feature of the splice module is the built-in loose tube over length management, which compared to conventional solutions saves an additional rack unit for the over length tray. The trunk cables are brought to the sub rack side and splitted there. This results in very short stripping lengths for the trunk cables. Due to the tML<sup>®</sup> compatibility also MPO/MTP<sup>®</sup> modules can be equipped in the same sub rack. The modular design of the tDF rack system offers maximum flexibility. The racks can be ordered customized completely preconfigured.



**tde<sup>®</sup> trans data elektronik GmbH**

**Headquarter address:**

Lingener Str. 2  
D-49626 Buppen/Ohrte  
Tel.: +49 5435 9511 0  
Fax.: +49 5435 9511 32

**Sales office address:**

Prinz-Friedrich-Karl-Str. 46  
D-44135 Dortmund  
Tel.: +49 231 914 36 99  
Fax.: +49 231 914 31 29

info@tde.de | www.tde.de

tDF<sup>®</sup> - FO flex tube holder 3U 12-fold for 6,4mm

## Technical Data

Type	Fan-out unit 12-fold with cover for 6.4mm flex tube for tDF <sup>®</sup> subrack
Dimensions	50 x 133.35 x 42mm (L x W x H)
Mounting	Vertical in the rack system by two screws
Cable catch	6-fold
Color	Black
	QS-Managementsystem ISO 9001, ISO 14001 and TL 9000

## Product variants & accessories

Art.-No.	Description
TDF-3U-AD-32	tDF <sup>®</sup> - Distance adapters 32mm for tDF <sup>®</sup> subrack
TDF-3U-BP	tDF <sup>®</sup> - Loose tube management (6,4mm flex tube) for tDF <sup>®</sup> subrack
TDF-3U-CR-3	tDF <sup>®</sup> - Cable guide holder metal, 3fold for tDF <sup>®</sup> subrack
TDF-FAN-OUT-3U-5	tDF <sup>®</sup> - FO cable fan-out complete unit 3U 24-fold for 5,0mm flex tube
TDF-FAN-OUT-3U-6.4	tDF <sup>®</sup> - FO cable fan-out complete unit 3U 12-fold for 6,4mm flex tube
TDF-FT-HOLDER-3U-5	tDF <sup>®</sup> - FO flex tube holder 3U 24-fold for 5,0mm
TDF-FT-HOLDER-3U-6.4	tDF <sup>®</sup> - FO flex tube holder 3U 12-fold for 6,4mm
TDF-SR-3U	tDF <sup>®</sup> - sub rack 19"/3U/84HP
TDF-SR-3U-BP	tDF <sup>®</sup> - sub rack 19"/3U/84HP with integrated loose tube management (6.4mm flex tube)